

# NEW 34○Y SERIES

## NAMUR SOLENOID VALVE



### Product Features

- Direct Mounting to Pneumatic Actuator
- Push-Lock Manual Override
- Single / Double / Centered Closed / Exhaust Center / Pressure Center
- Aluminum valve body, 1/4" Pipe size (G connection)

※ Note : Port thread Rc, NPT. are also available on request


### Mechanical Characteristics

- Body : Aluminum
- Spool : Aluminum
- Enclosure : EEx m II T4 (Optional)

### Electrical Characteristics

- Coil Insulation Class : F

※ Note : H coil available on request

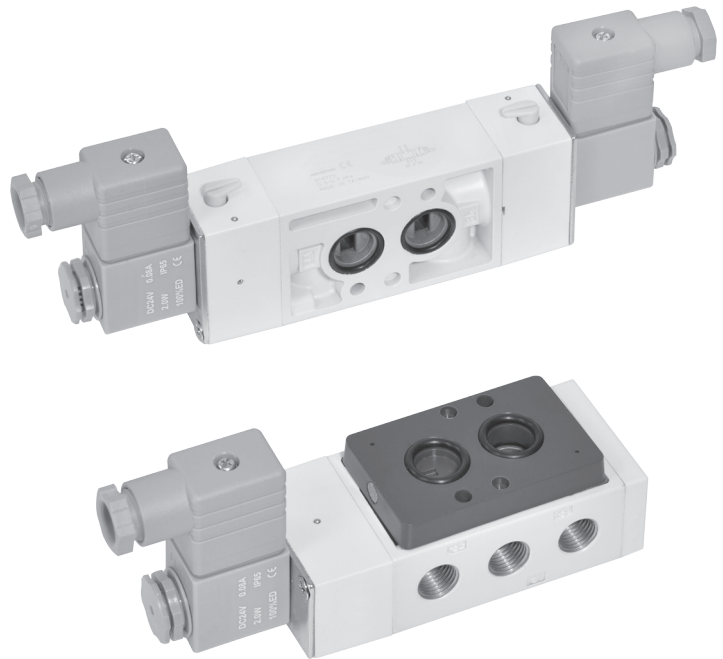

(with Plate)

※ Note : The actual color may differ from the image

### Ordering System

	<b>34</b>	<b>1</b>	<b>Y</b>	-	<b>02</b>	-	<b>220V</b>	-	<b>DL</b>
<b>SERIES Name</b> NAMUR	<b>Function</b> 1 : Single Solenoid 2 : Double Solenoid 3 : Center Closed 4 : Exhaust Center 5 : Pressure Center				<b>Port Size</b> 02: G 1/4		<b>Voltage</b> Blank : No Coil 24V : DC24V 110V : AC110V (50/60 Hz) 220V : AC220V (50/60 Hz)		<b>Wiring</b> Blank : Lead Wire D : DIN Connector DL : DIN Connector W/ Lamp
									<b>Plate</b> Part No. <b>341Y-A</b>




ENGINEERING YOUR SUCCESS.


# NEW 34○Y SERIES

## NAMUR SOLENOID VALVE


### Dimension 341Y-02

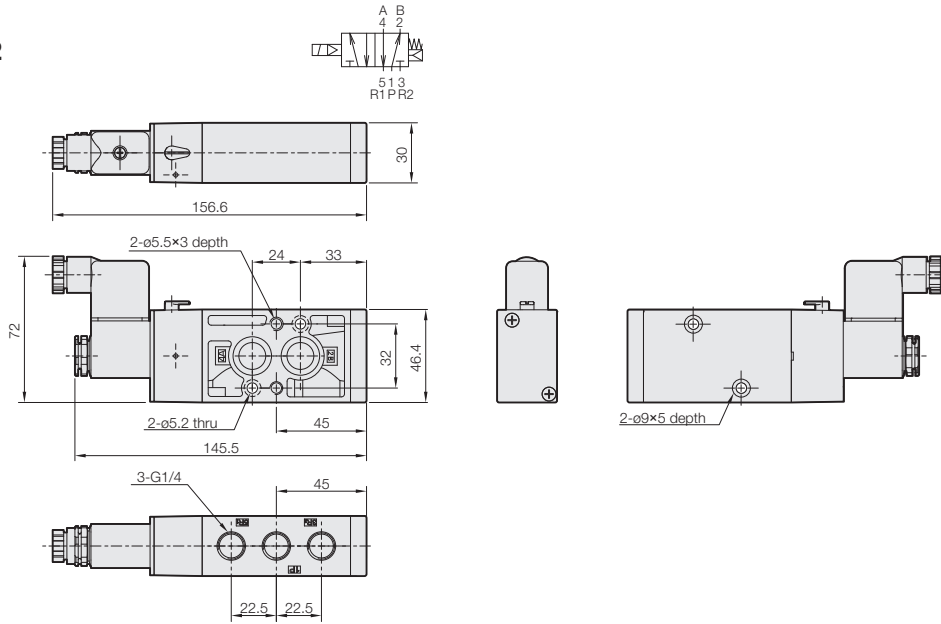

### Dimension 342Y-02

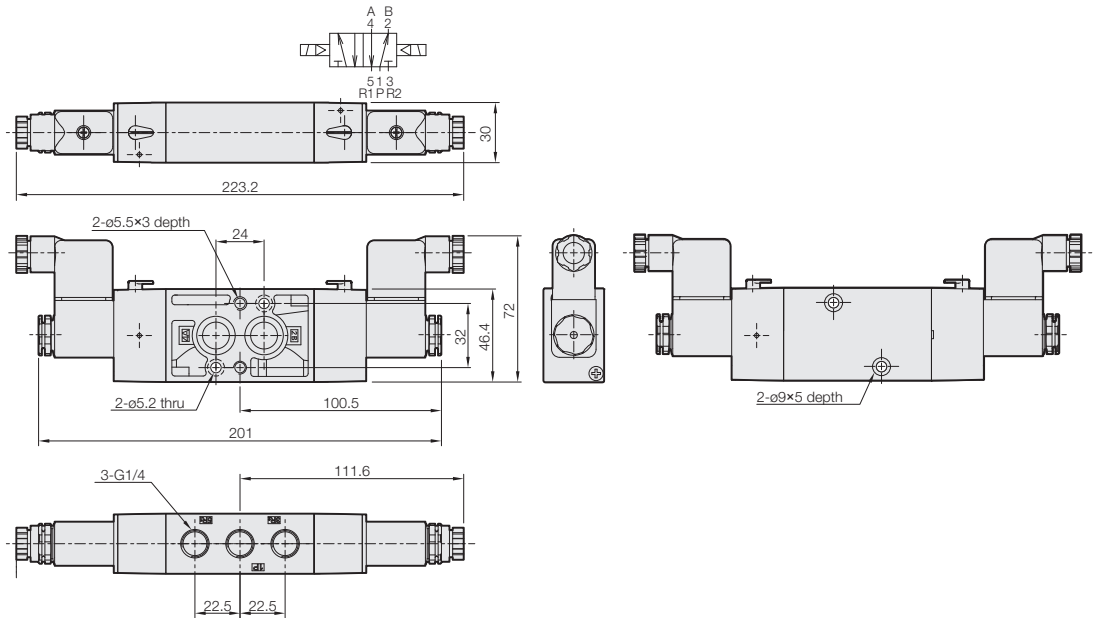

### Dimension 341Y-A

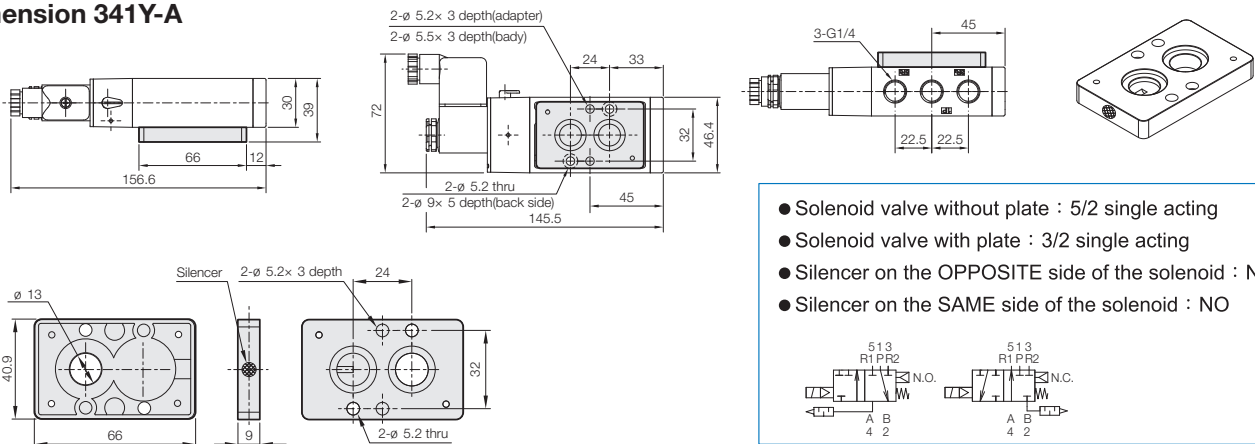

- Solenoid valve without plate : 5/2 single acting
- Solenoid valve with plate : 3/2 single acting
- Silencer on the OPPOSITE side of the solenoid : NC
- Silencer on the SAME side of the solenoid : NO



파카코리아주식회사  
 오토메이션 코리아 디비전  
 경기도 화성시 장안면 장안공단 1길 23  
 Tel: (031) 379 0220 Fax: (031) 379 2349  
 www.parker.com

ENGINEERING YOUR SUCCESS.