
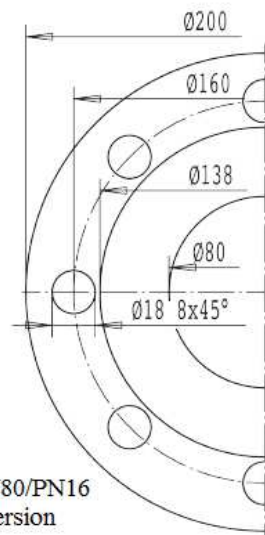


The GSN3 includes an integrated indicator port (U14M thread type) below the IN-connection

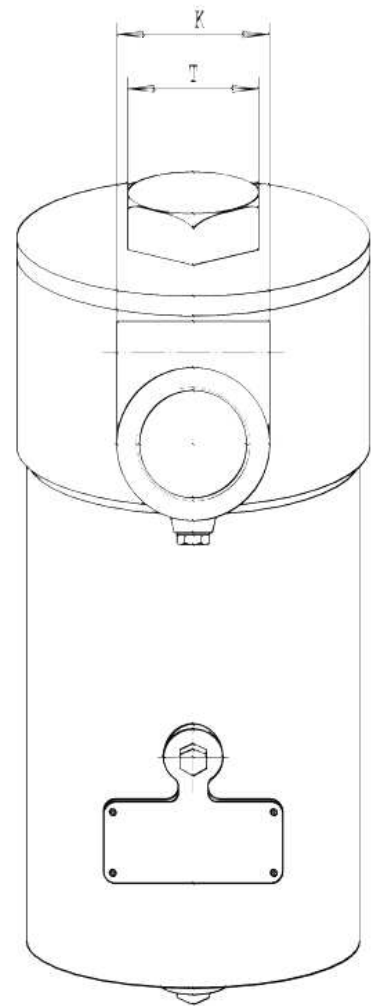

Optional flange DN80/PN16 for the GS7-D80 version

Type	A	D	F	G	H	J	K	L	M	N	P	R	S	T	U
GSN3	150	G1	170	27	83	125	45	280	11	108	71	118	159	32	200
GS6	190	G1½	230	38	112	170	64	350	13	148	106	139	180	55	210
GS7	260	G1½	230	38	112	170	64	420	13	148	106	139	180	55	240
GS7-D80	260	80	310	-	112	-	200	420	-	148	106	139	180	55	240