


# Interchange Element Data Sheet

Data sheet created using the Parker Par Fit Toolkit software.

<b>Creation Date:</b>	03/08/2018
<b>Datasheet No:</b>	DS185W
<b>Parker Part No:</b>	930192Q
<b>OEM:</b>	Pall
<b>OEM Part No:</b>	HC9800FKP8H&Z

### Product Dimensions

<b>A (mm)</b>	50.5	<b>(inch)</b>	1.99
<b>B (mm)</b>	24.5	<b>(inch)</b>	0.96
<b>D (mm)</b>	50.5	<b>(inch)</b>	1.99
<b>E (mm)</b>	208.0	<b>(inch)</b>	8.19

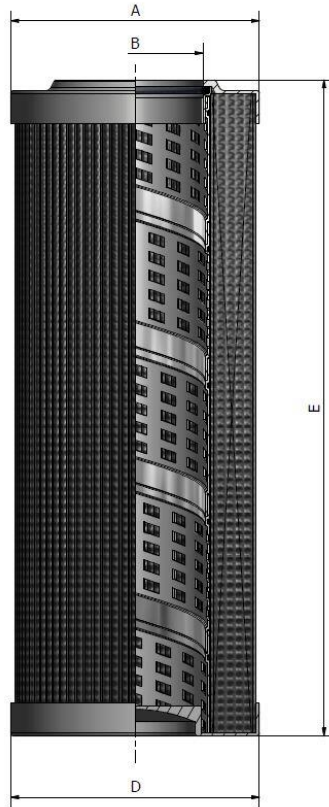

### Construction Materials

<b>Seal(s):</b>	FPM: Fluoroelastomer
<b>Top Endcap:</b>	Mild steel tin plated
<b>Bottom Endcap:</b>	Mild steel tin plated
<b>Inner Support Cylinder:</b>	Mild steel tin plated
<b>Filter Media:</b>	Multilayer fibreglass with coated mesh on both sides

### Calculated Performance Criteria

<b>Differential Pressure (<math>\Delta p</math>):</b>	0.32 bar @ 300 l/min
<b>Tested to ISO3968 @ 32 cSt</b>	4.64 psi @ 65.99 gpm
<b>Efficiency:</b>	>Beta 200 @ N/A microns & greater >Beta 1000 @ 4.5 microns & greater
<b>Minimum Collapse Pressure:</b>	>20 bar
<b>Tested to ISO2941</b>	>290 psi
<b>Dirt Holding Capacity acc. to ISO16889</b>	>24.9 gram @ 7 bar terminal pressure drop >24.9 gram @ 102 psi terminal pressure drop