


0207

Female Pipe Adapter
NPTF / NPSM Swivel

SAE 140131

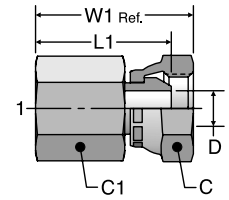

TUBE FITTING PART #	END SIZE		C HEX (in.)	C1 HEX (in.)	D DRILL (in.)	L1 (in.)	W1 (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 NPTF	2 NPSM						-S	-SS	-B
0207-2-2	1/8 - 27	1/8 - 27	9/16	9/16	0.156	0.87	1.02	6.0	6.0	3.3
0207-2-4	1/8 - 27	1/4 - 18	11/16	11/16	0.219	1.15	1.33	6.0	6.0	3.3
0207-4-2	1/4 - 18	1/8 - 27	9/16	11/16	0.156	1.17	1.32	6.0	6.0	3.3
0207-4-4	1/4 - 18	1/4 - 18	11/16	11/16	0.219	1.25	1.43	6.0	6.0	3.3
0207-6-4	3/8 - 18	1/4 - 18	11/16	7/8	0.219	1.31	1.49	6.0	6.0	3.3
0207-6-6	3/8 - 18	3/8 - 18	7/8	7/8	0.344	1.31	1.51	6.0	6.0	3.3
0207-6-8	3/8 - 18	1/2 - 14	1	1	0.469	1.35	1.64	5.0	5.0	3.3
0207-8-4	1/2 - 14	1/4 - 18	11/16	1	0.219	1.52	1.70	5.0	5.0	3.3
0207-8-6	1/2 - 14	3/8 - 18	7/8	1	0.344	1.53	1.73	5.0	5.0	3.3
0207-8-8	1/2 - 14	1/2 - 14	1	1	0.469	1.50	1.79	5.0	5.0	3.3
0207-12-8	3/4 - 14	1/2 - 14	1	1 1/4	0.469	1.56	1.85	4.0	4.0	2.6
0207-12-12	3/4 - 14	3/4 - 14	1 1/4	1 1/4	0.641	1.62	1.97	4.0	4.0	2.6
0207-16-12	1 - 11 1/2	3/4 - 14	1 1/4	1 1/2	0.641	1.93	2.28	3.0	3.0	1.9
0207-16-16	1 - 11 1/2	1 - 11 1/2	1 1/2	1 1/2	0.844	2.00	2.37	3.0	3.0	1.9
0207-20-20	1 1/4 - 11 1/2	1 1/4 - 11 1/2	1 7/8	1 7/8	1.141	2.00	2.38	2.5	2.5	1.6
0207-24-24	1 1/2 - 11 1/2	1 1/2 - 11 1/2	2 1/8	2 1/8	1.359	2.00	2.42	2.0	2.0	1.3
0207-32-32	2 - 11 1/2	2 - 11 1/2	2 5/8	2 5/8	1.813	2.12	2.55	1.5	1.5	1.0

Dimensions and pressures for reference only, subject to change.

