


2207

Female Pipe Elbow
NPTF / NPSM Swivel

SAE 140231

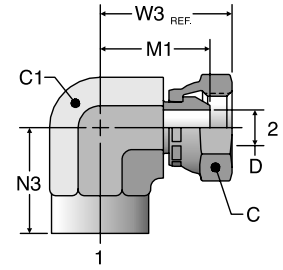

TUBE FITTING PART #	END SIZE		C HEX (in.)	C1 HEX (in.)	D DRILL (in.)	M1 (in.)	N3 (in.)	W3 (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 NPTF	2 NPSM							-S	-SS	-B
2207-2-2	1/8 - 27	1/8 - 27	9/16	9/16	0.156	0.80	0.66	0.95	5.0	5.0	3.3
2207-4-4	1/4 - 18	1/4 - 18	11/16	3/4	0.219	0.99	0.88	1.17	5.0	5.0	3.3
2207-4-6	1/4 - 18	3/8 - 18	7/8	7/8	0.344	0.95	0.88	1.26	4.5	4.5	2.9
2207-6-6	3/8 - 18	3/8 - 18	7/8	7/8	0.344	1.06	1.02	1.26	4.5	4.5	2.9
2207-8-6	1/2 - 14	3/8 - 18	7/8	1 1/16	0.344	1.14	1.37	1.34	3.0	3.0	1.9
2207-8-8	1/2 - 14	1/2 - 14	1	1 1/16	0.469	1.24	1.23	1.53	3.0	3.0	1.9
2207-12-12	3/4 - 14	3/4 - 14	1 1/4	1 5/16	0.641	1.47	1.36	1.82	3.0	3.0	1.9
2207-16-16	1 - 11 1/2	1 - 11 1/2	1 1/2	1 5/8	0.844	1.73	1.62	2.10	1.8	1.8	1.1
2207-20-20	1 1/4 - 11 1/2	1 1/4 - 11 1/2	1 7/8	1 7/8	1.141	1.83	1.70	2.21	1.5	1.5	1.0
2207-24-24	1 1/2 - 11 1/2	1 1/2 - 11 1/2	2 1/8	2 1/2	1.359	2.41	2.08	2.83	1.5	1.5	1.0
2207-32-32	2 - 11 1/2	2 - 11 1/2	2 5/8	2 13/16	1.813	2.57	2.39	3.00	1.1	1.1	0.7

Dimensions and pressures for reference only, subject to change.

