


3507

45° Straight Thread Elbow
SAE-ORB / NPSM Swivel

SAE 140357

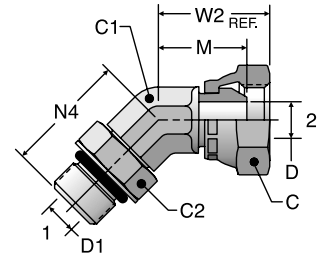

TUBE FITTING PART #	END SIZE		C HEX (in.)	C1 HEX (in.)	C2 HEX (in.)	D DRILL (in.)	D1 DRILL (in.)	M (in.)	N4 (in.)	W2 (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 UN/UNF-2A	2 NPSM									-S	-SS	-B
3507-4-4	7/16 - 20	1/4 - 18	11/16	7/16	9/16	0.219	0.172	0.61	1.05	0.79	6.0	6.0	3.3
3507-6-4	9/16 - 18	1/4 - 18	11/16	9/16	11/16	0.219	0.297	0.76	1.11	0.94	6.0	6.0	3.3
3507-6-6	9/16 - 18	3/8 - 18	7/8	9/16	11/16	0.344	0.297	0.83	1.14	1.03	6.0	6.0	3.3
3507-6-8	9/16 - 18	1/2 - 14	1	3/4	11/16	0.469	0.297	0.87	1.08	1.16	5.0	5.0	3.3
3507-8-6	3/4 - 16	3/8 - 18	7/8	3/4	7/8	0.344	0.391	0.82	1.30	1.02	6.0	6.0	3.3
3507-8-8	3/4 - 16	1/2 - 14	1	3/4	7/8	0.469	0.391	0.82	1.30	1.18	5.0	5.0	3.3
3507-8-12	3/4 - 16	3/4 - 14	1 1/4	3/4	7/8	0.641	0.391	1.02	1.41	1.37	3.0	3.0	1.9
3507-10-6	7/8 - 14	3/8 - 18	7/8	1 1/16	1	0.344	0.484	0.78	1.35	0.98	5.0	5.0	3.3
3507-10-8	7/8 - 14	1/2 - 14	1	7/8	1	0.469	0.484	0.88	1.52	1.17	5.0	5.0	3.3
3507-10-12	7/8 - 14	3/4 - 14	1 1/4	1 1/16	1	0.641	0.484	1.05	1.36	1.40	3.0	3.0	1.9
3507-12-8	1 1/16 - 12	1/2 - 14	1	1 1/16	1 1/4	0.469	0.609	0.83	1.73	1.12	5.0	5.0	3.3
3507-12-12	1 1/16 - 12	3/4 - 14	1 1/4	1 1/16	1 1/4	0.641	0.609	1.02	1.73	1.37	3.0	3.0	1.9
3507-16-16	1 5/16 - 12	1 - 1 1/2	1 1/2	1 5/16	1 1/2	0.844	0.844	1.15	1.86	1.52	2.5	2.5	1.6

Dimensions and pressures for reference only, subject to change.

