


# 5607

Long Male Pipe Elbow  
NPTF / NPSM Swivel

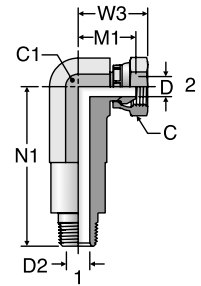

TUBE FITTING PART #	END SIZE		C HEX (in.)	C1 HEX (in.)	D DRILL (in.)	D2 DRILL (in.)	M1 (in.)	N1 (in.)	W3 (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 NPTF	2 NPSM								-S	-SS	-B
	5607-2-2	1/8 - 27								1/8 - 27	9/16	9/16
5607-4-4	1/4 - 18	1/4 - 18	11/16	3/4	0.219	0.281	0.98	2.25	1.16	6.0	6.0	3.3
5607-6-6	3/8 - 18	3/8 - 18	7/8	7/8	0.344	0.406	1.00	2.76	1.20	6.0	6.0	3.3
5607-8-8	1/2 - 14	1/2 - 14	1	1 1/16	0.469	0.531	1.19	3.19	1.48	5.0	5.0	3.3
5607-12-12	3/4 - 14	3/4 - 14	1 1/4	1 5/16	0.641	0.719	1.34	3.66	1.69	3.0	3.0	1.9
5607-16-16	1 - 11 1/2	1 - 11 1/2	1 1/2	1 7/8	0.844	0.938	1.78	4.31	2.15	2.5	2.5	1.6

Dimensions and pressures for reference only, subject to change.

