


# AOG5JG5

Straight Thread Run Tee  
SAE-ORB (all three ends)

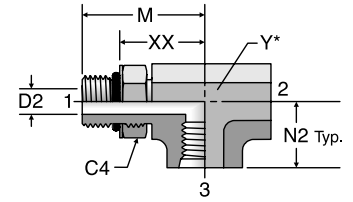

\* Y – Across wrench flats

TUBE FITTING PART #	END SIZE			C4 HEX (in.)	D2 DRILL (in.)	M (in.)	N2 (in.)	XX AFTER ASSY (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI)		
	1	2	3							-S	-SS	-B
	UN/UNF-2A	UN/UNF-2B	UN/UNF-2B									
4 AOG5JG5	7/16 - 20	7/16 - 20	7/16 - 20	9/16	0.172	1.23	0.74	0.84	3/4	6.0	6.0	3.3
6 AOG5JG5	9/16 - 18	9/16 - 18	9/16 - 18	11/16	0.297	1.38	0.86	0.96	7/8	5.0	5.0	3.3
8 AOG5JG5	3/4 - 16	3/4 - 16	3/4 - 16	7/8	0.391	1.59	1.03	1.10	1 1/16	4.0	4.0	2.6
10 AOG5JG5	7/8 - 14	7/8 - 14	7/8 - 14	1	0.484	1.81	1.18	1.25	1 1/16	2.5	2.5	1.6
12 AOG5JG5	1 1/16 - 12	1 1/16 - 12	1 1/16 - 12	1 1/4	0.609	2.00	1.39	1.35	1 5/16	2.5	2.5	1.6
16 AOG5JG5	1 5/16 - 12	1 5/16 - 12	1 5/16 - 12	1 1/2	0.844	2.25	1.52	1.60	1 5/8	2.5	2.5	1.6

Dimensions and pressures for reference only, subject to change.