


C3MX

Male Elbow – BSPT
37° Flare / BSPT

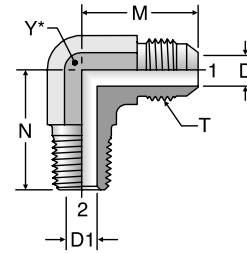

Y* – Across wrench flats

TUBE FITTING PART #	END SIZE			T TUBE END UN/UNF-2A	D (mm)	D1 (mm)	M (mm)	N (mm)	Y (mm)	Dynamic Pressure (x 1,000 PSI)		
	1		2							S	SS	B
	(mm)	(in.)										
4C3MX	6	1/4	1/8 - 28	7/16 - 20	4.4	4.8	22.6	19.8	11	4.5	4.5	2.9
4-4C3MX	6	1/4	1/4 - 19	7/16 - 20	4.4	4.8	26.6	27.7	14	4.5	4.5	2.9
5C3MX	8	5/16	1/8 - 28	1/2 - 20	6.0	4.8	24.1	19.8	13	4.5	4.5	2.9
5-4C3MX	8	5/16	1/4 - 19	1/2 - 20	6.0	7.0	26.6	27.7	14	4.5	4.5	2.9
6C3MX	10	3/8	1/4 - 19	9/16 - 18	7.5	7.0	26.9	27.7	14	4.5	4.5	2.9
6-6C3MX	10	3/8	3/8 - 19	9/16 - 18	7.5	10.3	29.0	31.0	19	4.5	4.5	2.9
6-8C3MX	10	3/8	1/2 - 14	9/16 - 18	7.5	13.5	31.0	37.3	22	4.5	4.5	2.9
8-4C3MX	12	1/2	1/4 - 19	3/4 - 16	9.9	7.0	31.8	31.0	19	4.5	4.5	2.9
8C3MX	12	1/2	3/8 - 19	3/4 - 16	9.9	10.3	31.8	31.0	19	4.5	4.5	2.9
8-8C3MX	12	1/2	1/2 - 14	3/4 - 16	9.9	13.5	33.8	37.3	22	4.5	4.5	2.9
10-6C3MX	14,15,16	5/8	3/8 - 19	7/8 - 14	12.3	10.3	36.5	32.5	22	4.5	4.5	2.9
10C3MX	14,15,16	5/8	1/2 - 14	7/8 - 14	12.3	13.5	36.8	37.3	22	4.5	4.5	2.9
10-12C3MX	14,15,16	5/8	3/4 - 14	7/8 - 14	12.3	18.0	39.2	40.4	27	2.3	2.3	1.5
12-8C3MX	18,20	3/4	1/2 - 14	1 1/16 - 12	15.5	13.5	42.2	40.4	27	4.5	4.5	2.9
12C3MX	18,20	3/4	3/4 - 14	1 1/16 - 12	15.5	18.0	42.2	40.4	27	2.3	2.3	1.5
16-12C3MX	25	1	3/4 - 14	1 5/16 - 12	21.5	18.0	46.0	45.2	33	2.3	2.3	1.5
16C3MX	25	1	1 - 11	1 5/16 - 12	21.5	23.8	46.0	50.0	33	2.3	2.3	1.5
20-16C3MX	30,32	1 1/4	1 - 11	1 5/8 - 12	27.5	23.8	52.3	59.7	41	2.3	2.3	1.5
20C3MX	30,32	1 1/4	1 1/4 - 11	1 5/8 - 12	27.5	31.7	52.3	60.5	41	2.3	2.3	1.5
24C3MX	38	1 1/2	1 1/2 - 11	1 7/8 - 12	33.0	38.0	59.2	67.1	48	2.3	2.0	1.3

Dimensions and pressures for reference only, subject to change.

