


# F3HG

Conversion Adapter  
NPTF / BSPT

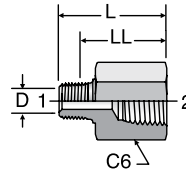

TUBE FITTING PART #	END SIZE		C6 HEX (in.)	D DRILL (in.)	L (mm)	LL REF (in.)	Dynamic Pressure (x 1,000 PSI)		
	1	2					-S	-SS	-B
	BSPT	NPTF							
1/8 x 1/8F3HG	1/8 - 28	1/8 - 27	9/16	0.188	1.08	0.84	6.0	6.0	3.3
1/4 x 1/4F3HG	1/4 - 19	1/4 - 18	3/4	0.281	1.37	1.03	6.0	6.0	3.3
3/8 x 3/8F3HG	3/8 - 19	3/8 - 19	7/8	0.406	1.38	1.04	6.0	6.0	3.3
1/2 x 1/2F3HG	1/2 - 14	1/2 - 14	1 1/8	0.531	1.88	1.42	5.0	5.0	3.3
3/4 x 3/4F3HG	3/4 - 14	3/4 - 14	1 3/8	0.719	1.95	1.49	4.0	4.0	2.6
1 x 1F3HG	1 - 11	1 - 11	1 5/8	0.938	2.38	1.79	3.0	3.0	1.9
1 1/2 x 1 1/2F3HG	1 1/2 - 11	1 1/2 - 11	2 3/8	1.437	2.53	1.59	2.0	2.0	1.3

Dimensions and pressures for reference only, subject to change.