


F3HG5

Conversion Adapter
BSPT / SAE-ORB

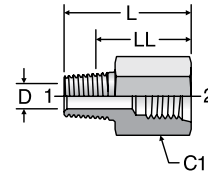

TUBE FITTING PART #	END SIZE		C1 HEX (in.)	D DRILL (in.)	L (in.)	LL AFTER ASSY (in.)	Dynamic Pressure (x 1,000 PSI)		
	1	2					-S	-SS	-B
	BSPT	UN/UNF-2B							
1/8-4F3HG5	1/8 - 28	7/16 - 20	11/16	0.188	1.09	0.86	6.0	6.0	3.3
1/8-5F3HG5	1/8 - 28	1/2 - 20	3/4	0.188	1.09	0.86	6.0	6.0	3.3
1/4-6F3HG5	1/4 - 19	9/16 - 18	13/16	0.281	1.36	1.02	6.0	6.0	3.3
3/8-8F3HG5	3/8 - 19	3/4 - 16	1	0.406	1.45	1.09	5.0	5.0	3.3
1/2-10F3HG5	1/2 - 14	7/8 - 14	1 1/8	0.531	1.78	1.32	4.5	4.5	2.9
3/4-12F3HG5	3/4 - 14	1 1/16 - 12	1 3/8	0.719	1.92	1.40	4.5	4.5	2.9
1-16F3HG5	1 - 11	1 5/16 - 12	1 5/8	0.938	2.13	1.54	3.5	3.5	2.2

Dimensions and pressures for reference only, subject to change.