


F4OHG5

Conversion Adapter
BSP-ORR / SAE-ORB
(for ISO 1179-1 / DIN 3852-2 Port)

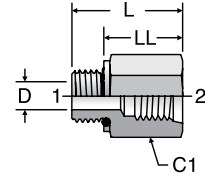

TUBE FITTING PART #	END SIZE		C1 HEX (in.)	D DRILL (in.)	L (in.)	LL AFTER ASSY (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 BSPP	2 UN/UNF-2B					-S	-SS	-B
1/8-4F4OHG5	1/8 - 28	7/16 - 20	11/16	0.172	1.00	0.75	5.0	5.0	3.3
1/4-4F4OHG5	1/4 - 19	7/16 - 20	3/4	0.297	1.11	0.89	5.0	5.0	3.3
1/4-6F4OHG5	1/4 - 19	9/16 - 18	13/16	0.297	1.25	0.89	5.0	5.0	3.3
3/8-4F4OHG5	3/8 - 19	7/16 - 20	7/8	0.391	1.19	0.75	5.0	5.0	3.3
3/8-5F4OHG5	3/8 - 19	1/2 - 20	7/8	0.391	1.19	0.75	5.0	5.0	3.3
3/8-6F4OHG5	3/8 - 19	9/16 - 18	7/8	0.391	1.25	0.89	5.0	5.0	3.3
3/8-8F4OHG5	3/8 - 19	3/4 - 16	1	0.391	1.33	0.97	5.0	5.0	3.3
1/2-10F4OHG5	1/2 - 14	7/8 - 14	1 1/8	0.484	1.60	1.14	3.5	3.5	2.2
3/4-12F4OHG5	3/4 - 14	1 1/16 - 12	1 3/8	0.609	1.74	1.28	3.5	3.5	2.2
1-16F4OHG5	1 - 11	1 5/16 - 12	1 3/4	0.844	1.92	1.33	3.5	3.5	2.2
1 1/4-16F4OHG5	1 1/4 - 11	1 5/16 - 12	2	1.078	1.95	1.22	2.0	2.0	1.3
1 1/4-20F4OHG5	1 1/4 - 11	1 5/8 - 12	2	1.078	1.95	1.36	2.0	2.0	1.3

Dimensions and pressures for reference only, subject to change.

