


# F687OMX

Swivel – ISO 6149 Connector  
37° Swivel / ISO 6149

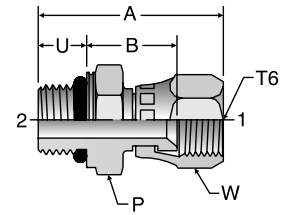

TUBE FITTING PART #	END SIZE			T6 TUBE END UN/UNF-2B	B (mm)	A (mm)	P (mm)	W (mm)	U (mm)	Dynamic Pressure (x 1,000 PSI)		
	1		2							S	SS	B
	(mm)	(in.)	Male Metric Parallel Thread									
4M10F687OMX	6	1/4	M10x1	7/16 - 20	15.0	31.9	14	14	8.5	7.2	5.0	3.3
5M12F687OMX	8	5/16	M12x1.5	1/2 - 20	16.8	35.6	17	17	11.0	6.0	5.0	3.3
6M14F687OMX	10	3/8	M14x1.5	9/16 - 18	18.0	37.2	19	19	11.0	5.0	5.0	3.3
8M16F687OMX	12	1/2	M16x1.5	3/4 - 16	21.0	41.8	22	22	11.5	5.0	5.0	3.3
10M22F687OMX	14, 15, 16	5/8	M22x1.5	7/8 - 14	23.0	47.6	27	27	13.0	5.0	5.0	3.3
12M27F687OMX	18, 20	3/4	M27x2	1 1/16 - 12	24.5	51.7	32	32	16.0	5.0	5.0	3.3
16M33F687OMX	25	1	M33x2	1 5/16 - 12	27.4	56.9	41	38	16.0	3.6	3.6	2.3

Dimensions and pressures for reference only, subject to change.