


FHG4

Conversion Adapter
NPTF / BSPP

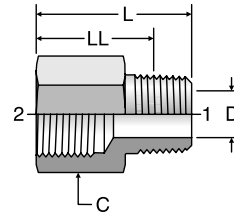

TUBE FITTING PART #	END SIZE		C HEX (in.)	D DRILL (in.)	L (in.)	LL (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 NPTF	2 BSPP					-S	-SS	-B
	1/4X1/4FHG4	1/4 - 18							
1/4X3/8FHG4	1/4 - 18	3/8 - 19	13/16	0.281	1.40	1.06	6.0	6.0	3.3
3/8X1/4FHG4	3/8 - 18	1/4 - 19	3/4	0.406	1.31	0.96	6.0	6.0	3.3
3/8X3/8FHG4	3/8 - 18	3/8 - 19	1	0.406	1.34	0.99	6.0	6.0	3.3
1/2X3/8FHG4	1/2 - 14	3/8 - 19	15/16	0.531	1.50	1.04	6.0	6.0	3.3
1/2X1/2FHG4	1/2 - 14	1/2 - 14	1 1/8	0.531	1.66	1.20	5.0	5.0	3.3
3/4X3/4FHG4	3/4 - 14	3/4 - 14	1 7/16	0.719	1.75	1.27	4.0	4.0	2.6

Dimensions and pressures for reference only, subject to change.