


# FHG5

Female Straight Thread Adapter  
NPTF / SAE-ORB

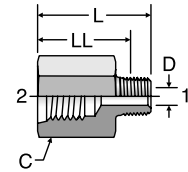

TUBE FITTING PART #	HOSE FITTING PART #	END SIZE		C HEX (in.)	D DRILL (in.)	L (in.)	LL AFTER ASSY (in.)	Dynamic Pressure (x 1,000 PSI)		
		1	2					-S	-SS	-B
		NPTF	UN/UNF-2B							
1/8-4 FHG5	0110-2-4	1/8 - 27	7/16 - 20	11/16	0.187	1.06	0.83	6.0	6.0	3.3
1/8-5 FHG5	0110-2-5	1/8 - 27	1/2 - 20	3/4	0.187	1.09	0.86	6.0	6.0	3.3
1/4-6 FHG5	0110-4-6	1/4 - 18	9/16 - 18	3/4	0.281	1.36	1.02	6.0	6.0	3.3
3/8-6 FHG5	0110-6-6	3/8 - 18	9/16 - 18	3/4	0.187	1.42	1.07	6.0	6.0	3.3
3/8-8 FHG5	0110-6-8	3/8 - 18	3/4 - 16	1	0.391	1.50	1.15	5.0	5.0	3.3
1/2-6 FHG5	0110-8-6	1/2 - 14	9/16 - 18	7/8	0.484	1.58	1.12	6.0	6.0	3.3
1/2-8 FHG5	0110-8-8	1/2 - 14	3/4 - 16	1	0.531	1.66	1.20	5.0	5.0	3.3
1/2-10 FHG5	0110-8-10	1/2 - 14	7/8 - 14	1 1/4	0.484	1.75	1.29	4.5	4.5	2.9
3/4-8 FHG5	0110-12-8	3/4 - 14	3/4 - 16	1 1/8	0.672	1.13	0.65	4.5	4.5	2.9
3/4-12 FHG5	0110-12-12	3/4 - 14	1 1/16 - 12	1 3/8	0.719	1.97	1.49	4.5	4.5	2.9
1-16 FHG5	0110-16-16	1 - 11 1/2	1 5/16 - 12	1 5/8	0.844	2.13	1.56	3.5	3.5	2.2

Dimensions and pressures for reference only, subject to change.