


# FNTX

Cap  
37° Flare

SAE 070112A

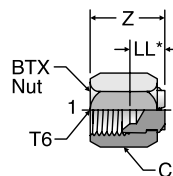

LL\* – End to base of mating flare-seat

TUBE FITTING PART #	HOSE FITTING PART #	END SIZE		C HEX (in.)	LL (in.)	Z (in.)	Dynamic Pressure (x 1,000 PSI)		
		1 (in.)	T6 UN/UNF-2B				-S	-SS	-B
2 FNTX	06CP-2	1/8	5/16 - 24	3/8	0.38	0.60	7.5	9.0	3.3
3 FNTX	06CP-3	3/16	3/8 - 24	7/16	0.38	0.66	7.5	9.0	3.3
4 FNTX	06CP-4	1/4	7/16 - 20	9/16	0.34	0.67	7.5	9.0	3.3
5 FNTX	06CP-5	5/16	1/2 - 20	5/8	0.41	0.77	6.0	7.2	3.3
6 FNTX	06CP-6	3/8	9/16 - 18	11/16	0.47	0.81	6.0	7.2	3.3
8 FNTX	06CP-8	1/2	3/4 - 16	7/8	0.53	0.94	6.0	7.2	3.3
10 FNTX	06CP-10	5/8	7/8 - 14	1	0.53	1.07	5.0	6.0	3.3
12 FNTX	06CP-12	3/4	1 1/16 - 12	1 1/4	0.66	1.24	5.0	6.0	3.3
14 FNTX	06CP-14	7/8	1 3/16 - 12	1 3/8	0.63	1.26	5.0	6.0	3.3
16 FNTX	06CP-16	1	1 5/16 - 12	1 1/2	0.63	1.29	4.5	5.4	2.9
20 FNTX	06CP-20	1 1/4	1 5/8 - 12	2	0.75	1.39	4.0	4.8	2.6
24 FNTX	06CP-24	1 1/2	1 7/8 - 12	2 1/4	0.94	1.70	3.0	3.6	2.0
32 FNTX	06CP-32	2	2 1/2 - 12	2 7/8	1.10	2.01	2.0	2.4	1.3

Dimensions and pressures for reference only, subject to change.