


G63P4

Swivel Female Connector
60° Swivel / BSPT

Mates with UT Style hose fittings

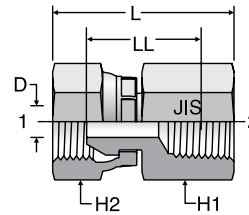

TUBE FITTING PART #	END SIZE		D DRILL (in.)	H1 HEX (in.)	H2 HEX (in.)	L (in.)	LL (in.)	Dynamic Pressure (x 1,000 PSI)
	1 BSPP	2 BSPT						S
4G63P4	1/4 - 19	1/4 - 19	0.177	0.75	0.75	1.61	1.16	5.0
6G63P4	3/8 - 19	3/8 - 19	0.275	0.88	0.88	1.78	1.28	5.0
8G63P4	1/2 - 14	1/2 - 14	0.433	1.06	1.06	2.02	1.42	5.0
12G63P4	3/4 - 14	3/4 - 14	0.625	1.44	1.44	2.20	1.50	4.0
16G63P4	1-11	1-11	0.828	1.63	1.63	2.52	1.80	3.0

Dimensions and pressures for reference only, subject to change.