


## G65L

Straight Thread Swivel  
Female Connector  
ORFS Swivel / SAE-ORB

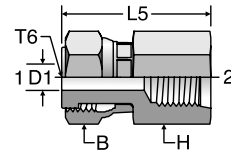

TUBE FITTING PART #	END SIZE		T6 SWIVEL UN/UNF-2B	B HEX (in.)	D1* DRILL (in.)	H HEX (in.)	L5 (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 UN/UNF-2B						-S	-SS
	4 G65L	1/4							
4-6 G65L	1/4	9/16 - 18	9/16 - 18	11/16	0.157	13/16	1.45	6.0	6.0
6-4 G65L	3/8	7/16 - 20	11/16 - 16	13/16	0.256	3/4	1.51	6.0	6.0
8-4 G65L	1/2	7/16 - 20	13/16 - 16	15/16	0.354	7/8	1.57	6.0	6.0

All o-rings and seals are shown in [Section N](#) of this catalog.

\* D1 nominal may vary from the values shown in the chart by 0.004 to 0.008.

Dimensions and pressures for reference only, subject to change.