


G6L

Female Pipe Thread Swivel
Connector
ORFS Swivel / NPTF

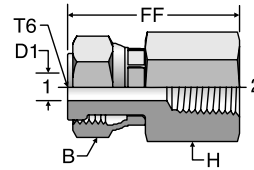

TUBE FITTING PART #	END SIZE		T6 SWIVEL UN/UNF-2B	D1* DRILL (in.)	FF (in.)	H (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 NPTF					-S	-SS
4-4 G6L	1/4	1/4 - 18	9/16 - 18	0.157	1.48	3/4	6.0	6.0
6 G6L	3/8	1/4 - 18	11/16 - 16	0.256	1.60	7/8	6.0	6.0
8-4 G6L	1/2	1/4 - 18	13/16 - 16	0.354	1.75	7/8	6.0	6.0

All o-rings and seals are shown in [Section N](#) of this catalog.

* D1 nominal may vary from the values shown in the chart by 0.004 to 0.008.

Dimensions and pressures for reference only, subject to change.