


G6X

Swivel Nut Female Connector
37° Swivel / NPTF

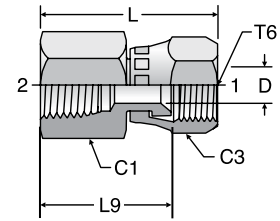

| TUBE FITTING PART # | HOSE FITTING PART # | END SIZE | | T6 SWIVEL UN/UNF-2B | C1 (in.) | C3 HEX (in.) | D (in.) | L (in.) | L9 (in.) | Dynamic Pressure (x 1,000 PSI) | | |
|---------------------|---------------------|----------|----------------|---------------------|----------|--------------|---------|---------|----------|--------------------------------|-----|-----|
| | | 1 (in.) | 2 NPTF | | | | | | | -S | -SS | -B |
| 4 G6X | 0206-2-4 | 1/4 | 1/8 - 27 | 7/16 - 20 | 9/16 | 9/16 | 0.172 | 1.27 | 0.92 | 6.0 | 6.0 | 3.3 |
| 4-4 G6X | 0206-4-4 | 1/4 | 1/4 - 18 | 7/16 - 20 | 3/4 | 9/16 | 0.172 | 1.43 | 1.08 | 6.0 | 6.0 | 3.3 |
| 6 G6X | 0206-4-6 | 3/8 | 1/4 - 18 | 9/16 - 18 | 3/4 | 11/16 | 0.297 | 1.44 | 1.06 | 5.0 | 5.0 | 3.3 |
| 6-6 G6X | 0206-6-6 | 3/8 | 3/8 - 18 | 9/16 - 18 | 7/8 | 11/16 | 0.267 | 1.54 | 1.16 | 5.0 | 5.0 | 3.3 |
| 6-8 G6X | 0206-8-6 | 3/8 | 1/2 - 14 | 9/16 - 18 | 1 1/8 | 11/16 | 0.297 | 1.80 | 1.42 | 5.0 | 5.0 | 3.3 |
| 8 G6X | 0206-6-8 | 1/2 | 3/8 - 18 | 3/4 - 16 | 7/8 | 7/8 | 0.391 | 1.69 | 1.23 | 5.0 | 5.0 | 3.3 |
| 8-8 G6X | 0206-8-8 | 1/2 | 1/2 - 14 | 3/4 - 16 | 1 1/8 | 7/8 | 0.391 | 1.94 | 1.48 | 5.0 | 5.0 | 3.3 |
| 10 G6X | 0206-8-10 | 5/8 | 1/2 - 14 | 7/8 - 14 | 1 1/8 | 1 | 0.484 | 1.98 | 1.47 | 5.0 | 5.0 | 3.3 |
| 12 G6X | 0206-12-12 | 3/4 | 3/4 - 14 | 1 1/16 - 12 | 1 3/8 | 1 1/4 | 0.610 | 2.01 | 1.51 | 4.0 | 4.0 | 2.6 |
| 12-8 G6X | 0206-8-12 | 3/4 | 1/2 - 14 | 1 1/16 - 12 | 1 1/4 | 1 1/4 | 0.610 | 2.00 | 1.50 | 5.0 | 5.0 | 3.3 |
| 16 G6X | 0206-16-16 | 1 | 1 - 11 1/2 | 1 5/16 - 12 | 1 5/8 | 1 1/2 | 0.844 | 2.48 | 1.85 | 3.0 | 3.0 | 2.0 |
| 20 G6X | 0206-20-20 | 1 1/4 | 1 1/4 - 11 1/2 | 1 5/8 - 12 | 2 | 2 | 1.078 | 2.86 | 2.17 | 2.5 | 2.5 | 1.6 |
| 24 G6X | 0206-24-24 | 1 1/2 | 1 1/2 - 11 1/2 | 1 7/8 - 12 | 2 3/8 | 2 1/4 | 1.312 | 3.01 | 2.26 | 2.0 | 2.0 | 1.3 |
| 32 G6X | 0206-32-32 | 2 | 2 - 11 1/2 | 2 1/2 - 12 | 2 7/8 | 2 7/8 | 1.781 | 3.40 | 2.45 | 1.5 | 1.5 | 1.0 |

Dimensions and pressures for reference only, subject to change.