


# GLO

Female NPT  
ORFS / Female Pipe

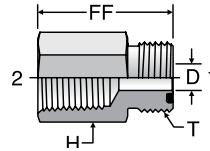

TUBE FITTING PART #	END SIZE		T UN/UNF-2A	D (in.)	FF (in.)	H HEX (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 NPTF					-S	-SS
	4 GLO	1/4					1/8 - 27	9/16 - 18
4-4 GLO	1/4	1/4 - 18	9/16 - 18	0.177	1.25	3/4	6.0	6.0
6 GLO	3/8	1/4 - 18	11/16 - 16	0.256	1.30	3/4	6.0	6.0
6-6 GLO	3/8	3/8 - 18	11/16 - 16	0.256	1.34	7/8	6.0	6.0
8 GLO	1/2	3/8 - 18	13/16 - 16	0.374	1.34	7/8	6.0	6.0

All o-rings and seals are shown in [Section N](#) of this catalog.

Dimensions and pressures for reference only, subject to change.