


GTX

Female Connector
37° Flare / NPTF

SAE 070103

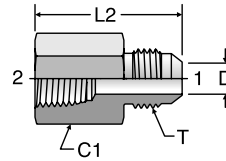

TUBE FITTING PART #	HOSE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C1 HEX (in.)	D DRILL (in.)	L2 (in.)	Dynamic Pressure (x 1,000 PSI)		
		1 (in.)	2 NPTF					-S	-SS	-B
2 GTX	0203-2-2	1/8	1/8 - 27	5/16 - 24	9/16	0.062	1.12	6.0	6.0	3.3
3 GTX	0203-2-3	3/16	1/8 - 27	3/8 - 24	9/16	0.125	1.13	6.0	6.0	3.3
4 GTX	0203-2-4	1/4	1/8 - 27	7/16 - 20	9/16	0.172	1.19	6.0	6.0	3.3
4-4 GTX	0203-4-4	1/4	1/4 - 18	7/16 - 20	3/4	0.172	1.39	6.0	6.0	3.3
4-6 GTX	0203-6-4	1/4	3/8 - 18	7/16 - 20	7/8	0.172	1.45	6.0	6.0	3.3
4-8 GTX	0203-8-4	1/4	1/2 - 14	7/16 - 20	1 1/8	0.172	1.68	6.0	6.0	3.3
5 GTX	0203-2-5	5/16	1/8 - 27	1/2 - 20	9/16	0.234	1.17	6.0	6.0	3.3
5-4 GTX	0203-4-5	5/16	1/4 - 18	1/2 - 20	3/4	0.234	1.39	6.0	6.0	3.3
6 GTX	0203-4-6	3/8	1/4 - 18	9/16 - 18	3/4	0.297	1.40	6.0	6.0	3.3
6-2 GTX	0203-2-6	3/8	1/8 - 27	9/16 - 18	5/8	0.297	1.19	6.0	6.0	3.3
6-6 GTX	0203-6-6	3/8	3/8 - 18	9/16 - 18	7/8	0.297	1.46	6.0	6.0	3.3
6-8 GTX	0203-8-6	3/8	1/2 - 14	9/16 - 18	1 1/8	0.297	1.69	5.0	5.0	3.3
8 GTX	0203-6-8	1/2	3/8 - 18	3/4 - 16	7/8	0.391	1.56	6.0	6.0	3.3
8-4 GTX	0203-4-8	1/2	1/4 - 18	3/4 - 16	13/16	0.391	1.55	6.0	6.0	3.3
8-8 GTX	0203-8-8	1/2	1/2 - 14	3/4 - 16	1 1/8	0.391	1.79	5.0	5.0	3.3
8-12 GTX	0203-12-8	1/2	3/4 - 14	3/4 - 16	1 3/8	0.391	1.85	4.0	4.0	2.6
10 GTX	0203-8-10	5/8	1/2 - 14	7/8 - 14	1 1/8	0.484	1.89	5.0	5.0	3.3
10-12 GTX	0203-12-10	5/8	3/4 - 14	7/8 - 14	1 3/8	0.484	1.95	4.0	4.0	2.6
12 GTX	0203-12-12	3/4	3/4 - 14	1 1/16 - 12	1 3/8	0.610	2.06	4.0	4.0	2.6
12-8 GTX	0203-8-12	3/4	1/2 - 14	1 1/16 - 12	1 1/8	0.610	2.05	5.0	5.0	2.6
12-16 GTX	0203-16-12	3/4	1 - 11 1/2	1 1/16 - 12	1 5/8	0.610	2.30	3.0	3.0	2.0
14 GTX	0203-12-14	7/8	3/4 - 14	1 3/16 - 12	1 3/8	0.718	2.06	4.0	4.0	2.6
16 GTX	0203-16-16	1	1 - 11 1/2	1 5/16 - 12	1 5/8	0.844	2.35	3.0	3.0	2.0
16-12 GTX	0203-12-16	1	3/4 - 14	1 5/16 - 12	1 3/8	0.844	2.13	4.0	4.0	2.6
16-20 GTX	0203-20-16	1	1 1/4 - 11 1/2	1 5/16 - 12	2	0.844	2.44	2.5	2.5	1.6
20 GTX	0203-20-20	1 1/4	1 1/4 - 11 1/2	1 5/8 - 12	2	1.078	2.49	2.5	2.5	1.6
20-16 GTX	0203-16-20	1 1/4	1 - 11 1/2	1 5/8 - 12	1 3/4	1.078	2.47	3.0	3.0	2.0
24 GTX	0203-24-24	1 1/2	1 1/2 - 11 1/2	1 7/8 - 12	2 3/8	1.312	2.62	2.0	2.0	1.3
32 GTX	0203-32-32	2	2 - 11 1/2	2 1/2 - 12	2 7/8	1.781	2.97	1.5	1.5	1.0

Dimensions and pressures for reference only, subject to change.

