


GTXO

Female Connector
37° Flare / NPTF

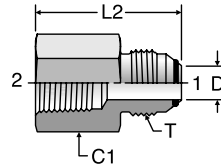

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C1 HEX (in.)	D DRILL (in.)	L2 (in.)	Dynamic Pressure (x 1,000 PSI)
	1 (in.)	2 NPTF					-SS
4 GTXO	1/4	1/8 - 27	7/16 - 20	9/16	0.156	1.20	6.0
6 GTXO	3/8	1/4 - 18	9/16 - 18	3/4	0.263	1.41	6.0
8 GTXO	1/2	3/8 - 18	3/4 - 16	7/8	0.391	1.58	6.0
10 GTXO	5/8	1/2 - 14	7/8 - 14	1 1/8	0.446	1.94	5.0
12 GTXO	3/4	3/4 - 14	1 1/16 - 12	1 3/8	0.585	2.10	4.8
16 GTXO	1	1 - 11 1/2	1 5/16 - 12	1 5/8	0.769	2.43	3.6
20 GTXO	1 1/4	1 1/4 - 11 1/2	1 5/8 - 12	2	1.020	2.56	3.0
24 GTXO	1 1/2	1 1/2 - 11 1/2	1 7/8 - 12	2 3/8	1.230	2.70	2.4

Dimensions and pressures for reference only, subject to change.