


HL6

Swivel Nut Union
ORFS Swivel / ORFS Swivel

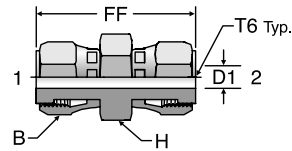

TUBE FITTING PART #	END SIZE		T6 SWIVEL UN/UNF-2B	B HEX (in.)	D1 DRILL (in.)	FF (in.)	H HEX (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 (in.)						-S	-SS
	4 HL6	1/4						1/4	9/16 - 18
6 HL6	3/8	3/8	11/16 - 16	13/16	0.256	1.77	3/4	9.2	9.2
8 HL6	1/2	1/2	13/16 - 16	15/16	0.354	2.12	7/8	9.2	9.2
10 HL6	5/8	5/8	1 - 14	1 1/8	0.453	2.42	1 1/16	6.0	6.0
12 HL6	3/4	3/4	1 3/16 - 12	1 3/8	0.551	2.74	1 1/4	6.0	6.0
16 HL6	1	1	1 7/16 - 12	1 5/8	0.787	2.95	1 7/16	6.0	6.0

All o-rings and seals are shown in [Section N](#) of this catalog.

* D1 nominal may vary from the values shown in the chart by 0.004 to 0.008.

Dimensions and pressures for reference only, subject to change.