


HMLO

Union – mm Hex
ORFS / ORFS

ISO 8434-3 S
SAE 52M0101

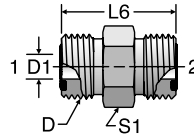

TUBE FITTING PART #	END SIZE 1 & 2		D TUBE END UN/UNF-2A	D1 DRILL (mm)	L6 (mm)	S1 HEX (mm)	Dynamic Pressure (x 1,000 PSI)	
	(mm)	(in.)					S	SS
4HMLO	6	1/4	9/16 - 18	4.5	27.5	17	9.2	9.2
6HMLO	8,10	3/8	11/16 - 16	6.5	31.0	19	9.2	9.2
8HMLO	12	1/2	13/16 - 16	9.5	35.5	22	9.2	9.2
10HMLO	14,15,16	5/8	1 - 14	12.5	42.5	27	6.0	6.0
12HMLO	18,20	3/4	1 3/16 - 12	15.5	47.0	32	6.0	6.0
16HMLO	22,25	1	1 7/16 - 12	20.5	49.5	41	6.0	6.0
20HMLO	28,30,32	1 1/4	1 11/16 - 12	26.0	51.5	46	6.0	6.0
24HMLO	35,38	1 1/2	2 - 12	32.0	53.0	55	5.0	5.0

All o-rings and seals are shown in [Section N](#) of this catalog.

Dimensions and pressures for reference only, subject to change.

