


HP4

Union
60° Cone

Mates with GU, G1 and G2 Style hose fittings

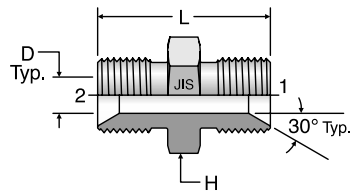

TUBE FITTING PART #	END SIZE	D DRILL (in.)	H HEX (in.)	L (in.)	Dynamic Pressure (x 1,000 PSI)
	1 & 2 BSPP				S
	4HP4				1/4 - 19
6HP4	3/8 - 19	0.275	0.88	1.50	5.0
8HP4	1/2 - 14	0.433	1.06	1.81	5.0
12HP4	3/4 - 14	0.625	1.44	2.05	4.0
16HP4	1-11	0.828	1.63	2.28	3.0

Dimensions and pressures for reference only, subject to change.