


# JMLO

Union Tee – mm Hex  
ORFS

ISO 8434-3 T  
SAE 52M0401

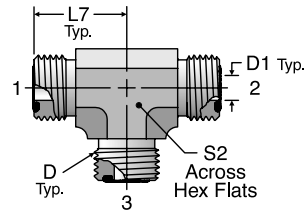

TUBE FITTING PART #	END SIZE		D TUBE END UN/UNF-2A	D1 DRILL (mm)	L7 (mm)	S2 (mm)	Dynamic Pressure (x 1,000 PSI)	
	1-3						S	SS
	(mm)	(in.)						
4JMLO	6	1/4	9/16 - 18	4.5	21.5	14	9.2	9.2
6JMLO	8,10	3/8	11/16 - 16	6.5	25.0	19	9.2	9.2
8JMLO	12	1/2	13/16 - 16	9.5	28.0	19	9.2	9.2
10JMLO	14,15,16	5/8	1 - 14	12.5	33.5	27	6.0	6.0
12JMLO	18,20	3/4	1 3/16 - 12	15.5	37.5	30	6.0	6.0
16JMLO	22,25	1	1 7/16 - 12	20.5	41.5	36	6.0	6.0
20JMLO	28,30,32	1 1/4	1 11/16 - 12	26.0	44.5	41	5.0	5.0
24JMLO	35,38	1 1/2	2 - 12	32.0	49.0	50	4.0	4.0

All o-rings and seals are shown in [Section N](#) of this catalog.

Dimensions and pressures for reference only, subject to change.