


JTXO

Union Tee
37° Flare (all three ends)

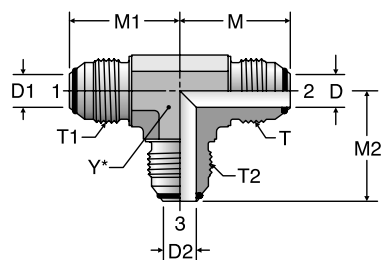

Y* – Across wrench flats

TUBE FITTING PART #	END SIZE	T TUBE END UN/UNF-2A	T1 TUBE END UN/UNF-2A	T2 TUBE END UN/UNF-2A	D DRILL (in.)	D1 DRILL (in.)	D2 DRILL (in.)	M (in.)	M1 (in.)	M2 (in.)	Y (in.)	Dynamic Pressure
	1 - 3 (in.)											(x 1,000 PSI)
4 JTXO	1/4	7/16 - 20	7/16 - 20	7/16 - 20	0.156	0.156	0.156	0.90	0.90	0.90	7/16	7.7
6 JTXO	3/8	9/16 - 18	9/16 - 18	9/16 - 18	0.263	0.263	0.263	1.08	1.08	1.08	9/16	6.0
8 JTXO	1/2	3/4 - 16	3/4 - 16	3/4 - 16	0.391	0.391	0.391	1.25	1.25	1.25	3/4	6.0
10 JTXO	5/8	7/8 - 14	7/8 - 14	7/8 - 14	0.446	0.446	0.446	1.50	1.50	1.50	7/8	5.0
12 JTXO	3/4	1 1/16 - 12	1 1/16 - 12	1 1/16 - 12	0.585	0.585	0.585	1.70	1.70	1.70	1 1/16	5.0
16 JTXO	1	1 5/16 - 12	1 5/16 - 12	1 5/16 - 12	0.769	0.769	0.769	1.89	1.89	1.89	1 5/16	5.0
20 JTXO	1 1/4	1 5/8 - 12	1 5/8 - 12	1 5/8 - 12	1.020	1.020	1.020	2.13	2.13	2.13	1 5/8	5.0
24 JTXO	1 1/2	1 7/8 - 12	1 7/8 - 12	1 7/8 - 12	1.230	1.230	1.230	2.41	2.41	2.41	1 7/8	5.0

Dimensions and pressures for reference only, subject to change.