


LOHL6

Tube End Extender / Expander
ORFS / ORFS Swivel

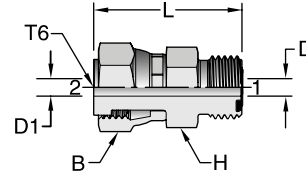

TUBE FITTING PART #	END SIZE		T6 SWIVEL UN/UNF-2B	B HEX (in.)	D* DRILL (in.)	D1* DRILL (in.)	L (in.)	H HEX (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 (in.)							-S	-SS
	4 LOHL6	1/4							1/4	9/16 - 18
6 LOHL6	3/8	3/8	11/16 - 16	13/16	0.256	0.256	1.44	3/4	9.2	9.2
6-4 LOHL6	3/8	1/4	9/16 - 18	11/16	0.157	0.157	1.37	3/4	9.2	9.2
8 LOHL6	1/2	1/2	13/16 - 16	15/16	0.374	0.354	1.67	7/8	9.2	9.2
8-6 LOHL6	1/2	3/8	11/16 - 16	13/16	0.374	0.256	1.62	7/8	9.2	9.2
10-8 LOHL6	5/8	1/2	13/16 - 16	15/16	0.492	0.354	1.81	1 1/16	6.0	6.0
12-10 LOHL6	3/4	5/8	1 - 14	1 1/8	0.610	0.453	1.99	1 1/4	6.0	6.0
16-12 LOHL6	1	3/4	1 3/16 - 12	1 3/8	0.807	0.551	2.16	1 1/2	6.0	6.0
20-16 LOHL6	1 1/4	1	1 7/16 - 12	1 5/8	1.024	0.787	2.28	1 3/4	5.0	5.0
24-20 LOHL6	1 1/2	1 1/4	1 11/16 - 12	1 7/8	1.260	1.024	2.35	2 1/8	4.0	4.0

All o-rings and seals are shown in [Section N](#) of this catalog.

* Manufacturer's option permits a single drill through equal to the smaller of D and D1.
D1 nominal may vary from the values shown in the chart by 0.004 to 0.008.

Dimensions and pressures for reference only, subject to change.

