


LOHQ2

Code 62 Flange Connector
Code 62 / ORFS

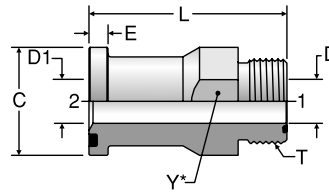

* Y – Across wrench flats

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C (in.)	D DRILL (in.)	D1 DRILL (in.)	E (in.)	L (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI) -S
	1 (in.)	2 Code 62								
12 LOHQ2	3/4	3/4	1 3/16-12	1.625	0.609	0.609	0.345	3.02	1 3/8	6.0
12-16 LOHQ2	3/4	1	1 3/16-12	1.875	0.609	0.609	0.375	3.34	1 5/8	6.0
16 LOHQ2	1	1	1 7/16-12	1.875	0.811	0.811	0.375	3.36	1 5/8	6.0
20 LOHQ2	1 1/4	1 1/4	1 11/16-12	2.125	1.024	1.024	0.405	3.48	1 7/8	5.0
24 LOHQ2	1 1/2	1 1/2	2-12	2.500	1.260	1.260	0.495	4.14	2 1/8	4.5

Dimensions and pressures for reference only, subject to change.