


# LOHX6

Swivel Adapter  
37° Flare Swivel / ORFS

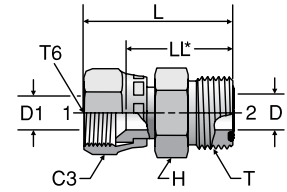

\* LL – End to base of flare

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	T6 SWIVEL UN/UNF-2B	C3 HEX (in.)	D DRILL (in.)	D1 DRILL (in.)	H HEX (in.)	L Ref. (in.)	LL Ref. (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 (in.)									-S	-SS
	4 LOHX6	1/4									1/4	9/16-18
6 LOHX6	3/8	3/8	11/16-16	9/16-18	11/16	0.264	0.264	3/4	1.5	1.06	5.0	6.0
8 LOHX6	1/2	1/2	13/16-16	3/4-16	7/8	0.374	0.374	7/8	1.8	1.21	5.0	6.0
10 LOHX6	5/8	5/8	1-14	7/8-14	1	0.484	0.484	1 1/16	2.0	1.40	5.0	6.0
12 LOHX6	3/4	3/4	1 3/16-12	1 1/16-12	1 1/4	0.609	0.609	1 1/4	2.2	1.48	5.0	6.0
16 LOHX6	1	1	1 7/16-12	1 5/16-12	1 1/2	0.807	0.807	1 1/2	2.4	1.64	3.6	4.3
20 LOHX6	1 1/4	1 1/4	1 11/16-12	1 5/8-12	2	1.024	1.078	1 3/4	2.6	1.77	3.6	4.3

Dimensions and pressures for reference only, subject to change.

