


MRO

Male Run Tee
NPTF (all three ends)

SAE 140424

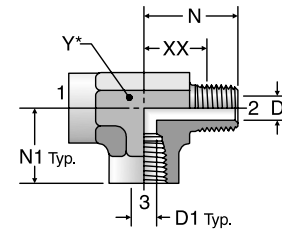

* Y – Across wrench flats

TUBE FITTING PART #	HOSE FITTING PART #	END SIZE 1-3 NPTF	D DRILL (in.)	REF D1 DRILL (in.)	N (in.)	N1 (in.)	XX AFTER ASSY (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI)		
									-S	-SS	-B
1/8 MRO	012T-2-2	1/8 - 27	0.188	0.328	0.78	0.66	0.55	9/16	5.0	5.0	3.2
1/4 MRO	012T-4-4	1/4 - 18	0.281	0.422	1.09	0.88	0.75	3/4	5.0	5.0	3.2
3/8 MRO	012T-6-6	3/8 - 18	0.406	0.563	1.22	1.02	0.87	7/8	4.5	4.5	3.0
1/2 MRO	012T-8-8	1/2 - 14	0.531	0.688	1.47	1.23	1.01	1 1/16	3.0	3.0	1.9
3/4 MRO	012T-10-10	3/4 - 14	0.719	0.891	1.59	1.36	1.11	1 5/16	3.0	3.0	1.9
1 MRO	012T-16-16	1 - 11 1/2	0.938	1.125	1.97	1.63	1.40	1 5/8	1.8	1.8	1.1
1 1/4 MRO	012T-20-20	1 1/4 - 11 1/2	1.250	1.469	2.38	1.70	1.11	1 7/8	1.5	1.5	1.0
1 1/2 MRO	012T-24-24	1 1/2 - 11 1/2	1.500	1.719	2.64	2.08	2.05	2 1/2	1.5	1.5	1.0

Dimensions and pressures for reference only, subject to change.

