


OBI2

Female Branch Tee
Intru-Lok / NPTF

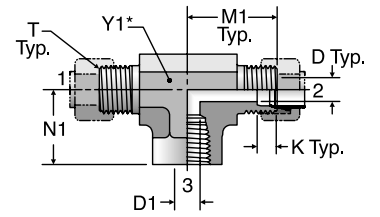

Y1* – Across wrench flats

| TUBE FITTING PART # | END SIZE | | | T TUBE END UN/UNF-2A | D DRILL (in.) | D1 DRILL (in.) | K (in.) | M1 (in.) | N1 (in.) | Y1 (in.) | Dynamic Pressure (x 1,000 PSI) |
|---------------------|----------|---------|----------|----------------------|---------------|----------------|---------|----------|----------|----------|--------------------------------|
| | 1 (in.) | 2 (in.) | 3 NPTF | | | | | | | | -B |
| 4 OBI2 | 1/4 | 1/4 | 1/8 - 27 | 7/16 - 20 | 0.203 | 0.328 | 0.23 | 0.72 | 0.53 | 9/16 | 1.5 |
| 4-4-4 OBI2 | 1/4 | 1/4 | 1/4 - 18 | 7/16 - 20 | 0.203 | 0.422 | 0.23 | 0.86 | 0.69 | 3/4 | 1.5 |
| 6 OBI2 | 3/8 | 3/8 | 1/4 - 18 | 9/16 - 18 | 0.282 | 0.422 | 0.25 | 0.92 | 0.69 | 3/4 | 1.5 |
| 8 OBI2 | 1/2 | 1/2 | 3/8 - 18 | 3/4 - 16 | 0.422 | 0.563 | 0.31 | 1.09 | 0.81 | 7/8 | 1.5 |

Dimensions and pressures for reference only, subject to change.

