


OTX

Female Branch Tee
37° Flare / 37° Flare / NPTF

SAE 070427

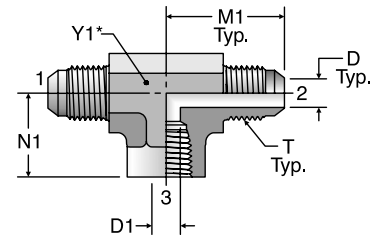

Y1* – Across wrench flats

TUBE FITTING PART #	HOSE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	D DRILL (in.)	D1 DRILL REF (in.)	M1 (in.)	N1 (in.)	Y1 (in.)	Dynamic Pressure (x 1,000 PSI)		
		1 & 2 (in.)	3 NPTF							-S	-SS	-B
4 OTX	223T-2-4	1/4	1/8 - 27	7/16 - 20	0.172	0.328	1.08	0.66	9/16	5.0	5.0	3.3
4-4-4 OTX	223T-4-4-4	1/4	1/4 - 18	7/16 - 20	0.172	0.422	1.13	0.88	3/4	5.0	5.0	3.3
5 OTX	223T-2-5	5/16	1/8 - 27	1/2 - 20	0.234	0.328	1.08	0.66	9/16	5.0	5.0	3.3
6 OTX	223T-4-6	3/8	1/4 - 18	9/16 - 18	0.297	0.422	1.23	0.88	3/4	5.0	5.0	3.3
6-6-6 OTX	223T-6-6-6	3/8	3/8 - 18	9/16 - 18	0.297	0.563	1.23	1.02	7/8	4.5	4.5	2.9
8 OTX	223T-6-8	1/2	3/8 - 18	3/4 - 16	0.391	0.563	1.42	1.02	7/8	4.5	4.5	2.9
8-8-8 OTX	223T-8-8-8	1/2	1/2 - 14	3/4 - 16	0.391	0.688	1.42	1.23	1 1/16	3.0	3.0	2.0
10 OTX	223T-8-10	5/8	1/2 - 14	7/8 - 14	0.484	0.688	1.64	1.23	1 1/16	3.0	3.0	2.0
12 OTX	223T-12-12	3/4	3/4 - 14	1 1/16 - 12	0.610	0.891	1.89	1.36	1 5/16	3.0	3.0	2.0
14 OTX	223T-12-14	7/8	3/4 - 14	1 3/16 - 12	0.718	0.891	1.86	1.42	1 5/16	3.0	3.0	2.0
16 OTX	223T-16-16	1	1 - 11 1/2	1 5/16 - 12	0.844	1.125	2.17	1.62	1 5/8	1.8	1.8	1.2
20 OTX	223T-20-20	1 1/4	1 1/4 - 11 1/2	1 5/8 - 12	1.078	1.469	2.33	1.70	1 7/8	1.5	1.5	1.0
24 OTX	223T-24-24	1 1/2	1 1/2 - 11 1/2	1 7/8 - 12	1.312	1.703	2.89	2.08	2 1/2	1.5	1.5	1.0

Dimensions and pressures for reference only, subject to change.

