


# PNMLO

Plug – mm Hex  
ORFS

ISO 8434-3 PL  
SAE 52M0109

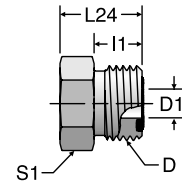

TUBE FITTING PART #	ORFS TUBE O.D.		D TUBE END UN/UNF-2A	D1 DRILL (mm)	I1 (mm)	L24 (mm)	S1 HEX (mm)	Dynamic Pressure (x 1,000 PSI)	
	(mm)	(in.)						S	SS
4PNMLO	6	1/4	9/16 - 18	4.5	10.0	16.5	17	9.2	9.2
6PNMLO	8,10	3/8	11/16 - 16	6.5	11.0	19.0	19	9.2	9.2
8PNMLO	12	1/2	13/16 - 16	9.5	13.0	22.0	22	9.2	9.2
10PNMLO	14,15,16	5/8	1 - 14	12.5	15.5	26.0	27	6.0	6.0
12PNMLO	18,20	3/4	1 3/16 - 12	15.5	17.0	27.5	32	6.0	6.0
16PNMLO	22,25	1	1 7/16 - 12	20.5	17.5	28.0	41	6.0	6.0
20PNMLO	28,30,32	1 1/4	1 11/16 - 12	26.0	17.5	28.0	46	6.0	6.0
24PNMLO	38	1 1/2	2 - 12	32.0	17.5	28.0	55	5.0	5.0

All o-rings and seals are shown in [Section N](#) of this catalog.

Dimensions and pressures for reference only, subject to change.