


R6BU

Swivel Nut Run Tee
Flareless / Flareless
Swivel

SAE 080432

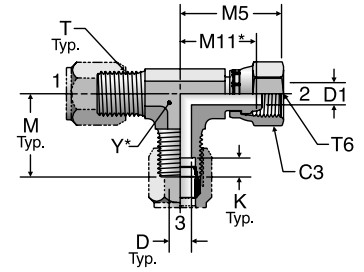

Y* – Across wrench flats

M11* – Center to end of mating part

TUBE FITTING PART #	END SIZE			T TUBE END UN/UNF-2A	T6 SWIVEL UN/UNF-2B	C3 HEX (in.)	D DRILL (in.)	D1 DRILL (in.)	K (in.)	M (in.)	M5 (in.)	M11 (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 (in.)	3 (in.)											-S	-SS
	4 R6BU	1/4	1/4											1/4	7/16 - 20
6 R6BU	3/8	3/8	3/8	9/16 - 18	9/16 - 18	11/16	0.282	0.282	0.26	1.05	1.25	.94	9/16	5.0	5.0
8 R6BU	1/2	1/2	1/2	3/4 - 16	3/4 - 16	7/8	0.422	0.422	0.31	1.25	1.38	1.13	3/4	5.0	5.0
12 R6BU	3/4	3/4	3/4	1 1/16 - 12	1 1/16 - 12	1 1/4	0.656	0.656	0.36	1.58	1.75	1.29	1 1/16	4.0	4.0
16 R6BU	1	1	1	1 5/16 - 12	1 5/16 - 12	1 1/2	0.875	0.875	0.42	1.73	2.00	1.43	1 5/16	3.0	3.0

Dimensions and pressures for reference only, subject to change.

