


S40MLO

Branch Tee – BSPP
(for ISO 1179-1 Port)
ORFS / ORFS / BSPP-ORR

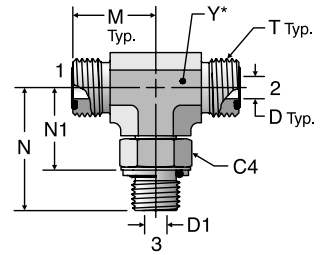

* Y – Across Wrench Flats

TUBE FITTING PART #	END SIZE			T TUBE END UN/UNF-2A	C4 HEX (mm)	D DRILL (mm)	D1 DRILL (mm)	M (mm)	N (mm)	N1 (mm)	Y (mm)	Dynamic Pressure (x 1,000 PSI)	
	1 & 2		3									S	SS
	(mm)	(in.)	BSPP										
4S40MLO	6	1/4	1/8 - 28	9/16 - 18	14	4.5	4.5	21.5	30.0	22.0	14	4.0	4.0
4-4-4S40MLO	6	1/4	1/4 - 19	9/16 - 18	19	4.5	7.5	23.5	36.0	24.5	19	4.0	4.0
6S40MLO	8,10	3/8	1/4 - 19	11/16 - 16	19	6.5	7.5	25.0	36.0	24.5	19	4.0	4.0
6-6-6S40MLO	8,10	3/8	3/8 - 19	11/16 - 16	22	6.5	10.0	26.5	38.0	27.0	19	4.0	4.0
8S40MLO	12	1/2	3/8 - 19	13/16 - 16	22	9.5	10.0	28.0	38.0	27.0	19	4.0	4.0
8-8-8S40MLO	12	1/2	1/2 - 14	13/16 - 16	27	9.5	12.5	31.0	48.5	34.0	27	4.0	4.0
10S40MLO	14,15,16	5/8	1/2 - 14	1 - 14	27	12.5	12.5	33.5	48.5	34.0	27	4.0	4.0
12S40MLO	18,20	3/4	3/4 - 14	1 3/16 - 12	36	15.5	15.5	37.5	51.5	36.5	30	4.0	4.0
16S40MLO	22,25	1	1 - 11	1 7/16 - 12	41	20.5	21.5	41.5	58.5	41.1	36	4.0	4.0

All o-rings and seals are shown in [Section N](#) of this catalog.

Dimensions and pressures for reference only, subject to change.

