


S6LO

Swivel Nut Branch Tee
ORFS / ORFS / ORFS Swivel

SAE 520433

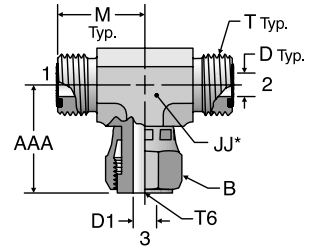

* JJ – Across Wrench Flats

TUBE FITTING PART #	END SIZE 1-3 (in.)	T TUBE END UN/UNF-2A	T6 SWIVEL UN/UNF-2B	AAA (in.)	B HEX (in.)	D DRILL (in.)	D1 DRILL (in.)	JJ (in.)	M (in.)	Dynamic Pressure (x 1,000 PSI)	
										-S	-SS
4 S6LO	1/4	9/16 - 18	9/16 - 18	1.07	11/16	0.177	0.157	9/16	0.85	9.2	9.2
6 S6LO	3/8	11/16 - 16	11/16 - 16	1.17	13/16	0.256	0.256	3/4	0.98	9.2	9.2
8 S6LO	1/2	13/16 - 16	13/16 - 16	1.50	15/16	0.374	0.354	3/4	1.10	9.2	9.2
10 S6LO	5/8	1 - 14	1 - 14	1.61	1 1/8	0.492	0.453	1 1/16	1.32	6.0	6.0
12 S6LO	3/4	1 3/16 - 12	1 3/16 - 12	1.83	1 3/8	0.610	0.551	1 3/16	1.48	6.0	6.0
16 S6LO	1	1 7/16 - 12	1 7/16 - 12	2.11	1 5/8	0.807	0.787	1 7/16	1.63	6.0	6.0
20 S6LO	1 1/4	1 11/16 - 12	1 11/16 - 12	2.28	1 7/8	1.024	1.024	1 5/8	1.75	5.0	5.0
24 S6LO	1 1/2	2 - 12	2 - 12	2.40	2 1/4	1.260	1.260	1 7/8	1.93	4.0	4.0

All o-rings and seals are shown in [Section N](#) of this catalog.

** Size 14 is not included in SAE J1453.

*** D1 nominal may vary from the values shown in the chart by 0.004 to 0.008.

Dimensions and pressures for reference only, subject to change.

