


S6MLO

Swivel Nut Branch Tee – mm Hex
ORFS / ORFS / ORFS Swivel

ISO 8434-3 SWBT
SAE 52M0433

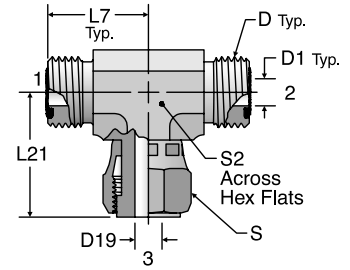

TUBE FITTING PART #	END SIZE		D TUBE END UN/UNF-2A	D1 DRILL (mm)	D19 DRILL (mm)	L7 (mm)	L21 (mm)	S HEX (mm)	S2 (mm)	Dynamic Pressure (x 1,000 PSI)	
	1-3									S	SS
	(mm)	(in.)									
4S6MLO	6	1/4	9/16 - 18	4.5	4.0	21.5	27.2	17	14		
6S6MLO	8,10	3/8	11/16 - 16	6.5	6.5	25.0	29.7	22	19	9.2	9.2
8S6MLO	12	1/2	13/16 - 16	9.5	9.0	28.0	38.0	24	19	9.2	9.2
10S6MLO	14,15,16	5/8	1 - 14	12.5	11.5	33.5	41.0	30	27	6.0	6.0
12S6MLO	18,20	3/4	1 3/16 - 12	15.5	14.0	37.5	46.5	36	30	6.0	6.0
16S6MLO	22,25	1	1 7/16 - 12	20.5	20.0	41.5	53.5	41	36	6.0	6.0
20S6MLO	28,30,32	1 1/4	1 11/16 - 12	26.0	26.0	44.5	58.0	50	41	4.0	4.0
24S6MLO	35,38	1 1/2	2 - 12	32.0	32.0	49.0	61.0	60	50	4.0	4.0

All o-rings and seals are shown in [Section N](#) of this catalog.

Dimensions and pressures for reference only, subject to change.