


S870MX

ISO 6149 Branch Tee

37° Flare / 37° Flare / ISO 6149

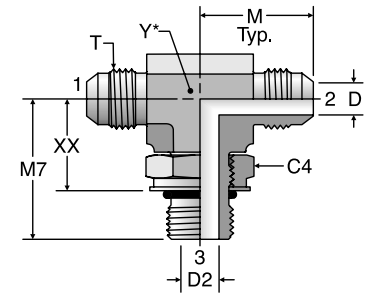

Y* – Across wrench flats

TUBE FITTING PART #	END SIZE			T TUBE END UN/UNF-2A	C4 (mm)	D (mm)	D2 (mm)	M (mm)	M7 (mm)	XX (mm)	Y (mm)	Dynamic Pressure (x 1,000 PSI)		
	1 & 2		3									S	SS	B
	(mm)	(in.)	Male Metric Parallel Thread											
6M14S870MX	10	3/8	M14 x 1.5	9/16 - 18	19	7.5	7.5	26.9	33.5	22.5	14	6.0	6.0	3.3
8M16S870MX	12	1/2	M16 x 1.5	3/4 - 16	22	9.9	9.0	31.8	38.0	26.5	19	5.0	5.0	3.3
10M22S870MX	14,15,16	5/8	M22 x 1.5	7/8 - 14	27	12.3	14.0	36.8	42.5	29.5	22	5.0	5.0	3.3
12M27S870MX	18,20	3/4	M27 x 2	1 1/16 - 12	32	15.5	18.0	42.2	51.0	35.0	27	5.0	5.0	3.3

Dimensions and pressures for reference only, subject to change.