


# SBI2

Male Branch Tee  
Intru-Lok / Intru-Lok / NPTF

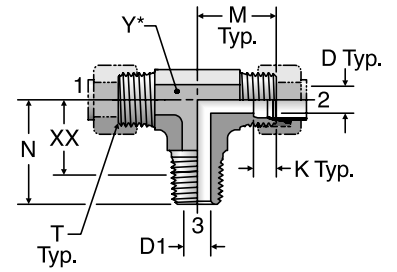

Y\* – Across wrench flats

TUBE FITTING PART #	END SIZE			T TUBE END UN/UNF-2A	D DRILL (in.)	D1 DRILL (in.)	K (in.)	M (in.)	N (in.)	XX AFTER ASSY (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI)
	1 (in.)	2 (in.)	3 NPTF									-B
2 SBI2	1/8	1/8	1/8 - 27	5/16 - 24	0.093	0.188	0.19	0.63	0.69	0.49	11/32	1.5
4 SBI2	1/4	1/4	1/8 - 27	7/16 - 20	0.203	0.188	0.23	0.63	0.69	0.64	3/8	1.5
4-4-4 SBI2	1/4	1/4	1/4 - 18	7/16 - 20	0.203	0.281	0.23	0.73	0.97	0.75	9/16	1.5
6 SBI2	3/8	3/8	1/4 - 18	9/16 - 18	0.282	0.281	0.25	0.72	0.91	0.75	9/16	1.5

Dimensions and pressures for reference only, subject to change.

