


# TRBU

Tube End Reducer  
Tube / Flareless

SAE 080123

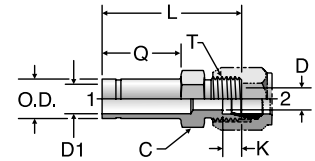

TUBE FITTING PART #	END SIZE		OD (in.)	T TUBE END UN/UNF-2A	C HEX (in.)	D DRILL (in.)	D1 DRILL (in.)	K (in.)	L (in.)	Q (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 (in.)									-S	-SS
	6-4 TRBU	3/8									1/4	0.38
8-4 TRBU	1/2	1/4	0.50	7/16 - 20	9/16	0.203	0.375	0.24	1.73	1.00	5.0	5.0
8-6 TRBU	1/2	3/8	0.50	9/16 - 18	5/8	0.281	0.375	0.26	1.77	1.00	5.0	5.0
10-6 TRBU	5/8	3/8	0.63	9/16 - 18	11/16	0.281	0.500	0.26	1.86	1.09	5.0	5.0
10-8 TRBU	5/8	1/2	0.63	3/4 - 16	13/16	0.422	0.500	0.31	1.95	1.09	4.5	4.5
12-6 TRBU	3/4	3/8	0.75	9/16 - 18	13/16	0.281	0.625	0.26	1.94	1.16	4.5	4.5
12-8 TRBU	3/4	1/2	0.75	3/4 - 16	13/16	0.422	0.625	0.31	2.03	1.16	4.5	4.5
12-10 TRBU	3/4	5/8	0.75	7/8 - 14	15/16	0.500	0.625	0.36	2.16	1.16	4.5	4.5
14-10 TRBU	7/8	5/8	0.88	7/8 - 14	15/16	0.500	0.875	0.36	2.14	1.16	4.0	4.0
16-8 TRBU	1	1/2	1.00	3/4 - 16	1 1/16	0.422	0.844	0.31	2.05	1.13	4.0	4.0
16-10 TRBU	1	5/8	1.00	7/8 - 14	1 1/16	0.500	0.844	0.36	2.11	1.13	4.0	4.0
16-12 TRBU	1	3/4	1.00	1 1/16 - 12	1 1/8	0.656	0.844	0.36	2.25	1.13	4.0	4.0
20-16 TRBU	1 1/4	1	1.25	1 5/16 - 12	1 3/8	0.875	1.031	0.42	2.28	1.16	3.0	3.0
24-12 TRBU	1 1/2	3/4	1.50	1 1/16 - 12	1 5/8	0.656	1.250	0.36	2.45	1.25	2.0	2.0
24-16 TRBU	1 1/2	1	1.50	1 5/16 - 12	1 5/8	0.875	1.250	0.42	2.45	1.25	2.0	2.0
24-20 TRBU	1 1/2	1 1/4	1.50	1 5/8 - 12	1 7/8	1.093	1.250	0.42	2.45	1.25	2.0	2.0

Dimensions and pressures for reference only, subject to change.

