


V3T4

45° Male Elbow
30° Flare / BSPT

Mates with FU Style hose fittings

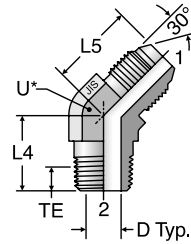

* U – Across wrench flats

TUBE FITTING PART #	END SIZE		D DRILL (in.)	L4 (in.)	L5 (in.)	TE (in.)	U (in.)	Dynamic Pressure (x 1,000 PSI)
	1 BSPP	2 BSPT						S
	4V3T4	1/4 - 19						1/4 - 19
6V3T4	3/8 - 19	3/8 - 19	0.275	0.87	0.97	0.33	0.75	5.0
8V3T4	1/2 - 14	1/2 - 14	0.433	1.06	1.10	0.43	0.88	5.0
12V3T4	3/4 - 14	3/4 - 14	0.625	1.18	1.24	0.48	1.06	4.0
16V3T4	1-11	1-11	0.828	1.37	1.26	0.55	1.31	3.0

Dimensions and pressures for reference only, subject to change.