


WB12

Bulkhead Union
Intru-Lok / Intru-Lok

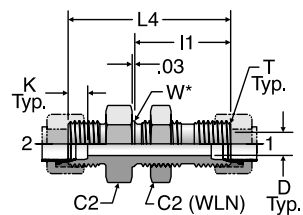

W* – Pilot drill diameter

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C2 HEX (in.)	D DRILL (in.)	I1 (in.)	K (in.)	L4 (in.)	W DIA (in.)	Dynamic Pressure (x 1,000 PSI)
	1 (in.)	2 (in.)								-B
4 WB12	1/4	1/4	7/16 - 20	9/16	0.203	0.88	0.23	1.34	0.44	1.5
6 WB12	3/8	3/8	9/16 - 18	11/16	0.282	0.94	0.25	1.56	0.56	1.5
8 WB12	1/2	1/2	3/4 - 16	7/8	0.422	1.06	0.31	1.75	0.75	1.5

Dimensions and pressures for reference only, subject to change.