


# XHLO

Male Adapter  
37° Flare / ORFS

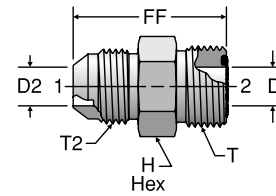

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	T2 TUBE END UN/UNF-2A	D* DRILL (in.)	D2* DRILL (in.)	FF (in.)	H HEX (in.)	Dynamic Pressure (x 1,000 PSI)	
	1 (in.)	2 (in.)							-S	-SS
	4 XHLO	1/4							1/4	9/16-18
6 XHLO	3/8	3/8	11/16-16	9/16-18	0.264	0.297	1.34	3/4	6.0	7.2
8 XHLO	1/2	1/2	13/16-16	3/4-16	0.378	0.391	1.55	7/8	6.0	7.2
10 XHLO	5/8	5/8	1-14	7/8-14	0.484	0.484	1.83	1 1/16	5.0	6.0
12 XHLO	3/4	3/4	1 3/16-12	1 1/16-12	0.609	0.609	2.05	1 1/4	5.0	6.0
16 XHLO	1	1	1 7/16-12	1 5/16-12	0.807	0.807	2.16	1 1/2	4.5	5.4
20 XHLO	1 1/4	1 1/4	1 11/16-12	1 5/8-12	1.024	1.024	2.29	1 3/4	4.0	4.8
24 XHLO	1 1/2	1 1/2	2-12	1 7/8-12	1.260	1.260	2.48	2 1/8	3.0	3.6

\*Manufacturing option permits a single drill through equal to the smaller of D and D2.

Dimensions and pressures for reference only, subject to change.

