


XHQ2

Code 62 Flange Connector
Code 62 / 37° Flare

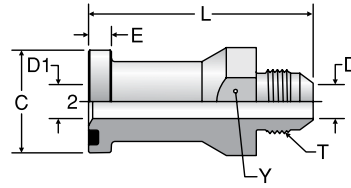

* Y – Across wrench flats

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C (in.)	D DRILL (in.)	D1 DRILL (in.)	E (in.)	L (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI)
	1 (in.)	2 Code 62								-S
12 XHQ2	3/4	3/4	1 1/16-12	1.625	0.609	0.609	0.345	3.08	1 3/8	5.0
16 XHQ2	1	1	1 5/16-12	1.875	0.844	0.844	0.375	3.43	1 5/8	5.0
20 XHQ2	1 1/4	1 1/4	1 5/8-12	2.125	1.078	1.078	0.405	3.60	1 7/8	4.0
24 XHQ2	1 1/2	1 1/2	1 7/8-12	2.500	1.312	1.312	0.495	4.34	2 1/8	3.0

Dimensions and pressures for reference only, subject to change.