


XHU86

EO Swivel Adapter
Metric Swivel (EO) / 37° Flare

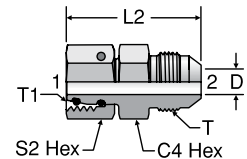

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	T1 Metric Thread	C4 HEX (in.)	S2 HEX (mm)	D DRILL (in.)	L2 (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 EO Swivel	2 (in.)							S	SS	B
L Series											
4-6L XHU86	6L	1/4	7/16-20	M12 X 1.5	1/2	14	0.098	1.52	4.5	4.5	2.9
6-8L XHU86	8L	3/8	9/16-18	M14 X 1.5	5/8	17	0.157	1.55	4.5	4.5	2.9
6-10L XHU86	10L	3/8	9/16-18	M16 X 1.5	5/8	19	0.236	1.57	4.5	4.5	2.9
8-12L XHU86	12L	1/2	3/4-16	M18 X 1.5	13/16	22	0.314	1.69	4.5	4.5	2.9
10-15L XHU86	15L	5/8	7/8-14	M22 X 1.5	15/16	27	0.394	1.95	4.5	4.5	2.9
12-18L XHU86	18L	3/4	1 1/16-12	M26 X 1.5	1 1/8	32	0.511	2.10	4.5	4.5	2.9
16-22L XHU86	22L	1	1 5/16-12	M30 X 2	1 3/8	36	0.669	2.29	2.3	2.3	1.5
16-28L XHU86	28L	1	1 5/16-12	M36 X 2	1 3/8	41	0.866	2.37	2.3	2.3	1.5
S Series											
4-6S XHU86	6S	1/4	7/16-20	M14 X 1.5	1/2	17	0.098	1.52	7.5	7.5	4.9
6-8S XHU86	8S	3/8	9/16-18	M16 X 1.5	5/8	19	0.157	1.57	7.5	7.5	4.9
6-10S XHU86	10S	3/8	9/16-18	M18 X 1.5	11/16	22	0.236	1.57	7.5	7.5	4.9
8-12S XHU86	12S	1/2	3/4-16	M20 X 1.5	13/16	24	0.314	1.75	6.0	6.0	3.9
10-16S XHU86	16S	5/8	7/8-12	M24 X 1.5	15/16	30	0.433	1.97	5.0	5.0	3.3
12-20S XHU86	20S	3/4	1 1/16-12	M30 X 2	1 1/8	36	0.551	2.26	5.0	5.0	3.3
16-25S XHU86	25S	1	1 5/16-12	M36 X 2	1 3/8	46	0.709	2.37	4.5	4.5	2.9

Dimensions and pressures for reference only, subject to change.

