


# XHX6

Extender and Expander  
37° Flare / 37° Flare Swivel

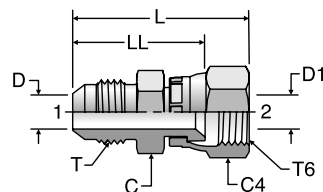

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	T6 SWIVEL UN/UNF-2B	C HEX (in.)	C4 HEX (in.)	D DRILL (in.)	D1 DRILL (in.)	L (in.)	LL (in.)	Dynamic Pressure (x 1,000 PSI)		
	1 (in.)	2 (in.)									-S	-SS	-B
	4 XHX6	1/4									1/4	7/16 - 20	7/16 - 20
6 XHX6	3/8	3/8	9/16 - 18	9/16 - 18	5/8	11/16	0.297	0.297	1.50	1.12	6.0	6.0	3.3
6-4 XHX6	3/8	1/4	9/16 - 18	7/16 - 20	5/8	9/16	0.297	0.172	1.50	1.16	6.0	6.0	3.3
8 XHX6	1/2	1/2	3/4 - 16	3/4 - 16	13/16	7/8	0.391	0.391	1.71	1.28	6.0	6.0	3.3
8-6 XHX6	1/2	3/8	3/4 - 16	9/16 - 18	13/16	11/16	0.391	0.297	1.72	1.34	6.0	6.0	3.3
10 XHX6	5/8	5/8	7/8 - 14	7/8 - 14	1	1	0.484	0.484	2.01	1.50	5.0	5.0	3.3
10-8 XHX6	5/8	1/2	7/8 - 14	3/4 - 16	15/16	7/8	0.484	0.391	1.93	1.50	5.0	5.0	3.3
12 XHX6	3/4	3/4	1 1/16 - 12	1 1/16 - 12	1 1/4	1 1/4	0.610	0.610	2.20	1.70	5.0	5.0	3.3
12-10 XHX6	3/4	5/8	1 1/16 - 12	7/8 - 14	1 1/8	1.00	0.610	0.484	2.19	1.69	5.0	5.0	3.3
16 XHX6	1	1	1 5/16 - 12	1 5/16 - 12	1 1/2	1 1/2	0.844	0.844	2.47	1.86	4.0	3.0	2.6
16-12 XHX6	1	3/4	1 5/16 - 12	1 1/16 - 12	1 1/2	1 1/4	0.844	0.610	2.24	1.74	4.0	3.0	2.6
20-16 XHX6	1 1/4	1	1 5/8 - 12	1 5/16 - 12	1 11/16	1 1/2	1.078	0.844	2.50	1.89	4.0	3.0	2.6

Dimensions and pressures for reference only, subject to change.

