


XVQ1

Code 61 Flange 45° Elbow
Code 61 / 37° Flare

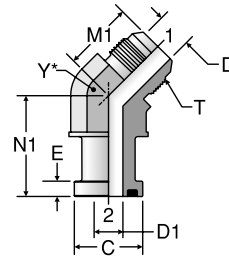

* Y – Across wrench flats

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C (in.)	D DRILL (in.)	D1 DRILL (in.)	E (in.)	M1 (in.)	N1 (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI) -S
	1 (in.)	2 (in.)									
12 XVQ1	3/4	3/4	1 1/16-12	1.500	0.609	0.609	0.265	1.27	1.58	1 7/16	5.0
16 XVQ1	1	1	1 5/16-12	1.750	0.844	0.844	0.315	1.47	1.85	1 5/8	5.0
20 XVQ1	1 1/4	1 1/4	1 5/8-12	2.000	1.078	1.078	0.315	1.59	2.40	1 7/8	4.0
24 XVQ1	1 1/2	1 1/2	1 7/8-12	2.375	1.312	1.312	0.315	1.78	2.90	2 1/2	3.0
32 XVQ1	2	2	2 1/2-12	2.812	1.781	1.781	0.375	2.22	3.00	2 1/2	2.0

Dimensions and pressures for reference only, subject to change.