


# XVQ2

Code 62 Flange 45° Elbow  
Code 62 / 37° Flare

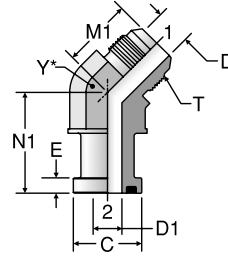

\* Y – Across wrench flats

TUBE FITTING PART #	END SIZE		T TUBE END UN/UNF-2A	C (in.)	D DRILL (in.)	D1 DRILL (in.)	E (in.)	M1 (in.)	N1 (in.)	Y (in.)	Dynamic Pressure (x 1,000 PSI) -S
	1 (in.)	2 (in.)									
12 XVQ2	3/4	3/4	1 1/16-12	1.625	0.609	0.609	0.345	1.27	1.83	1 7/16	5.0
16 XVQ2	1	1	1 5/16-12	1.875	0.844	0.844	0.375	1.47	2.07	1 5/8	5.0
20 XVQ2	1 1/4	1 1/4	1 5/8-12	2.125	1.078	1.078	0.405	1.59	2.40	1 7/8	4.0
24 XVQ2	1 1/2	1 1/2	1 7/8-12	2.500	1.312	1.312	0.495	1.78	2.90	2 1/2	3.0

Dimensions and pressures for reference only, subject to change.

